


# Vacuum filter VAF-PK-4

Part number: 15889

**FESTO**

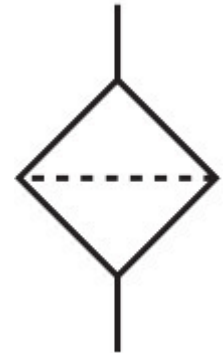

## Data sheet

Feature	Value
Nominal width	3 mm
Mounting position	Any
Grade of filtration	50 µm
Operating pressure	-0.95 bar...0 bar
Information on operating pressure	Only for use in open vacuum systems
Flow rate at negative pressure = -0.75 bar	70 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7::-]
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Suitability for the production of Li-ion batteries	Product corresponds to Festo's internal product definition for use in battery production: Metals with more than 1% by mass of copper, zinc or nickel are excluded from use. The exceptions are nickel in steel, chemically nickel-plated surfaces, circuit boards, cables, electrical plug connectors and coils
Ambient temperature	0 °C...40 °C
Product weight	6 g
Type of mounting	Line installation
Pneumatic connection	PK-4 with union nut
Material of union nut	POM
Note on materials	RoHS-compliant
Compressed air filter material	Fabric PA
Housing material	PA
Ejector pulse suitability	8 bar