
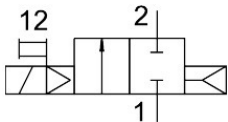


Air solenoid valve MN1H-2-1-MS-NPT

Part number: 161733

FESTO

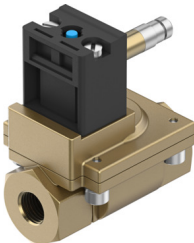

Data sheet

| Feature | Value |
|--|--|
| Structural design | Diaphragm valve |
| Sealing principle | Soft |
| Mounting position | Any |
| Type of mounting | Line installation |
| Fitting connection | 1 NPT |
| Nominal width | 25 mm |
| Valve function | 2/2, closed, monostable |
| Manual override | Detenting via accessory Non-detenting |
| Flow direction | Non-reversible |
| Medium | Filtered compressed air, 200 µm filter mesh |
| Exhaust air function | Without flow control option |
| Reset method | Pneumatic spring |
| Type of control | Pilot-controlled |
| Medium pressure | 0.5 bar...10 bar |
| Information on operating and pilot media | Operation with oil lubrication possible (required for further use) |
| Temperature of medium | -10 °C...60 °C |
| Ambient temperature | -10 °C...60 °C |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Material of screws | High-alloy stainless steel |
| Material number of screw | 1.4301 |
| Product weight | 1100 g |
| Degree of protection | IP65 |