 



OR gate OS-1/8-B-CT

Part number: 165694

FESTO

Run-out type. Available until 2010.

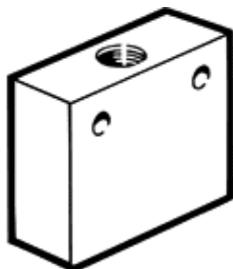

Data sheet

Feature	Value
Valve function	OR function
Pneumatic connection, port 1	G1/8
Pneumatic connection, port 2	G1/8
Mounting type	with through hole
Standard nominal flow rate	500 l/min
Working pressure	1 ... 10 bar
Ambient temperature	-10 ... 60 °C
Materials information, housing	Aluminum
Operating medium	Compressed air, filtered, unlubricated Filtered, lubricated air
Nominal size	4 mm
Medium temperature	-10 ... 60 °C
Pneumatic connection, port 3	G1/8
Materials note	Free of copper and PTFE
Materials information for seals	NBR