


# Bus interface SPC200-COM-PDP

Part number: 170224

FESTO

With PROFIBUS DP connection.

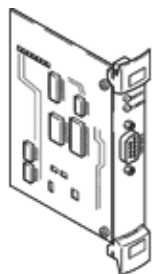

## Data sheet

Feature	Value
Configuration support	Device database file
Typical current consumption, plug-in module	50 mA
Product weight	80 g
Maximum address volume for outputs	32 byte
Maximum address volume for inputs	32 byte
Fieldbus interface address range	1 ... 125
Fieldbus interface design	Electrical isolation RS 485 9,6kBaud - 12 Mbaud DPV0: cyclical communication
Electrical connection, fieldbus interface	Plug socket SUB-D 9-pin
Installation space	From 3 up 4 or more with MMI