


**Air line lubricator**  
**LOE-3/4-D-MIDI-NPT**  
Part number: 173825

**FESTO**

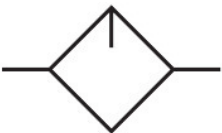

**Data sheet**

Feature	Value
Max. oil capacity	110 cm <sup>3</sup>
Bowl guard	Metal bowl guard
Operating pressure	1.6 MPa 16 bar 232 psi
Minimum flow rate for lubricator function	8 l/min
Standard nominal flow rate	6300 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4] Inert gas
Information on operating and pilot media	Operation with oil lubrication not possible
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-10 °C...60 °C
Air quality class at the output	Compressed air as per ISO 8573-1:2010 [7:4:-] Inert gas
Temperature of medium	-10 °C...60 °C
Ambient temperature	-10 °C...60 °C
Type of mounting	With accessories
Pneumatic connection 1	3/4 NPT
Pneumatic connection 2	3/4 NPT
Note on materials	RoHS-compliant
Material of bowl	PC