


Branching module
FRM-1/2-D-MIDI-NPT
Part number: 173928

FESTO

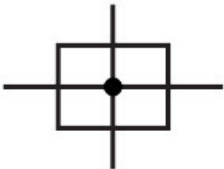

Data sheet

Feature	Value
Mounting position	Any
Structural design	Branching module
Operating pressure	0 MPa...1.6 MPa 0 bar...16 bar
Standard nominal flow rate in main flow direction 1 -> 2	8200 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7::-] Inert gas
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-10 °C...60 °C
Air quality class at the output	Compressed air as per ISO 8573-1:2010 [7::-] Inert gas
Temperature of medium	-10 °C...60 °C
Ambient temperature	-10 °C...60 °C
Product weight	502 g
Pneumatic connection 1	1/2 NPT
Pneumatic connection 2	1/2 NPT
Pneumatic connection 3	G1/2
Pneumatic connection 4	G1/4
Note on materials	RoHS-compliant
Housing material	Die-cast aluminum