 



Branching module FRM-H-3/8-D-MIDI-NPT

Part number: 173935

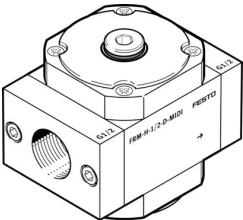

Data sheet

Feature	Value
Mounting position	Any
Structural design	Branching module
Operating pressure	0.02 MPa...1.6 MPa 0.2 bar...16 bar
Standard nominal flow rate in main flow direction 1 -> 2	4900 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-] Inert gas
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-10 °C...60 °C
Air quality class at the output	Compressed air as per ISO 8573-1:2010 [7:-:-] Inert gas
Temperature of medium	-10 °C...60 °C
Ambient temperature	-10 °C...60 °C
Product weight	526 g
Pneumatic connection 1	3/8 NPT
Pneumatic connection 2	3/8 NPT
Pneumatic connection 3	G1/2
Pneumatic connection 4	G1/4
Note on materials	RoHS-compliant
Housing material	Die-cast aluminum