


# Clevis flange SNC-32

Part number: 174383

FESTO

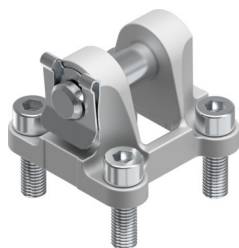

## Data sheet

| Feature                          | Value                                                                     |
|----------------------------------|---------------------------------------------------------------------------|
| Size                             | 32                                                                        |
| Based on norm                    | ISO 15552 (previously also VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290) |
| Corrosion resistance class (CRC) | 1 - Low corrosion stress                                                  |
| LABS (PWIS) conformity           | VDMA24364-B2-L                                                            |
| Ambient temperature              | -40 °C...150 °C                                                           |
| Max. load capacity               | 0.9 kN                                                                    |
| Product weight                   | 93 g                                                                      |
| Note on materials                | RoHS-compliant                                                            |
| Mounting material                | Die-cast aluminum                                                         |
| Bolt material                    | Steel<br>Galvanized                                                       |
| Material of screws               | Steel<br>Galvanized                                                       |
| Fuse material                    | Spring steel<br>Galvanized                                                |