


Clevis flange SNC-50

Part number: 174385

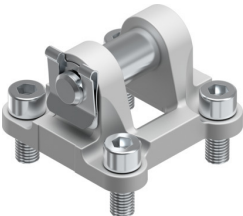

Data sheet

Feature	Value
Size	50
Based on norm	ISO 15552 (previously also VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-40 °C...150 °C
Max. load capacity	2.5 kN
Product weight	234 g
Note on materials	RoHS-compliant
Mounting material	Die-cast aluminum
Bolt material	Steel Galvanized
Material of screws	Steel Galvanized
Fuse material	Spring steel Galvanized