


Clevis flange SNCS-80

Part number: 174401

FESTO

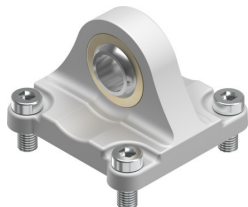

Data sheet

Feature	Value
Size	80
Based on norm	ISO 15552 (previously also VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-40 °C...150 °C
Max. load capacity	6 kN
Product weight	557 g
Note on materials	RoHS-compliant
Mounting material	Die-cast aluminum
Rod end bearing material	Steel PTFE
Material of screws	Steel Galvanized