


Clevis flange SNCL-32

Part number: 174404

FESTO

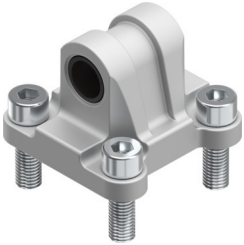

Data sheet

Feature	Value
Size	32
Based on norm	ISO 15552 (previously also VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-40 °C...90 °C
Max. load capacity	0.9 kN
Product weight	71 g
Note on materials	RoHS-compliant
Mounting material	Die-cast aluminum
Material of bearing	Polymer
Material of screws	Steel Galvanized