


**Motor flange**  
**EAMF-A-44A-60G/H**  
Part number: 1780430

**FESTO**

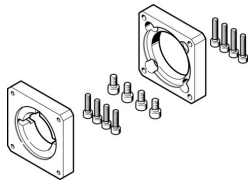

**Data sheet**

| Feature                          | Value          |
|----------------------------------|----------------|
| Mounting position                | Any            |
| LABS (PWIS) conformity           | VDMA24364-B2-L |
| Storage temperature              | -25 °C...60 °C |
| Relative air humidity            | 0 - 95 %       |
| Ambient temperature              | -10 °C...60 °C |
| Product weight                   | 178 g          |
| Interface code, motor in         | 60G<br>60H     |
| Interface code, coupling housing | 44A            |
| Note on materials                | RoHS-compliant |