


Pressure gauge MA-23-6-R1/8

Part number: 183896

FESTO

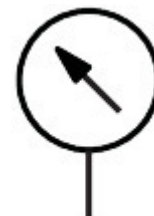

Data sheet

Feature	Value
Display range	0 bar...6 bar 1 psi...87 psi
Pressure gauge nominal size	23
Structural design	Bourdon tube pressure gauge
Type of mounting	Line installation
Operating medium	Inert gas Neutral liquids
Information on operating and pilot media	No acetylene No oxygen
Operating pressure	0 MPa...0.6 MPa 0 bar...6 bar 0 psi...87 psi
Intermittent load factor	0.6
Measurement accuracy class	4
Degree of protection	IP44
Temperature of medium	-20 °C...60 °C
Ambient temperature	-20 °C...60 °C
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Note on materials	RoHS-compliant
Connection position	Centered on rear side
Pneumatic connection	R1/8
Materials in contact with the media	Brass
Material of screwed plug	Brass
Housing material	Brass
Inspection window material	PC
Housing colour	Black
Product weight	27 g
Scale	Double scale bar (außen) psi (internal)