

Non-return valve HAM-1/16-QS-5/32-U

Part number: 190940


FESTO

Flow rate from the male thread to the QS plug connector.

This product is only available if ordered from the Festo Corporation, USA.

This type is suitable for vacuum.

Type to be discontinued. Available until 2011.

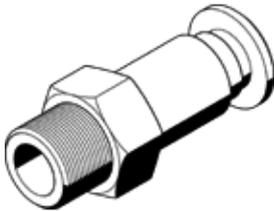

Data sheet

| Feature | Value |
|--------------------------------|--|
| Valve function | Non-return function |
| Pneumatic connection, port 1 | NPT1/16-27 |
| Pneumatic connection, port 2 | QS-5/32 |
| Mounting type | Threaded |
| Working pressure | -1 ... 10 bar |
| Ambient temperature | 0 ... 60 °C |
| Materials information, housing | Brass |
| Operating medium | Compressed air, filtered, unlubricated Filtered, lubricated air |
| Product weight | 12 g |