


Vacuum cup without connector

ESV-40-BN

Part number: 191060

FESTO

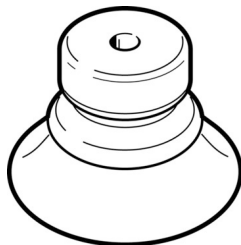

Data sheet

Feature	Value
Suction cup height compensation	9.5 mm
Min. workpiece radius	90 mm
Suction cup diameter	40 mm
Suction cup volume	11.699 cm ³
Connection position	Top
Mounting position	Any
Suction cup shape	Round bellows, 1.5 convolutions
Operating pressure	-95 kPa...0 kPa -0.95 bar...0 bar -13.775 psi...0 psi
Nominal operating pressure	-70 kPa -0.7 bar -10.15 psi
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:::]
LABS (PWIS) conformity	VDMA24364-A1-L
For use in the food industry	See supplementary material information
Ambient temperature	-10 °C...70 °C
Holding force at nominal operating pressure	52.3 N
Product weight	9.8 g
Color	Black
Shore hardness	50 +/- 5
Note on materials	RoHS-compliant
Suction cup material	NBR