


Plug socket with cable KMF-1-24-10-LED

Part number: 193458

FESTO

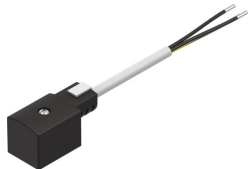

Data sheet

| Feature | Value |
|--|---|
| Switching position indication | LED |
| Type of mounting | On air solenoid valve with M3 central screw |
| Mounting position | Any |
| Product weight | 620 g |
| Electrical connection | Socket |
| Nominal operating voltage DC | 24 V |
| Protective earth connection | Available |
| Cable length | 10 m |
| Cable diameter | 6 mm |
| Cable design | 3 x 0.75 mm ² |
| Degree of protection | IP67 as per IEC 60529 |
| Ambient temperature | -20 °C...80 °C |
| CE marking (see declaration of conformity) | As per EU RoHS directive |
| UKCA marking (see declaration of conformity) | To UK RoHS instructions |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Material of cable sheath | PVC |
| Housing material | PC POM |
| Material of pin contacts | Bronze |