


**Manifold**  
**MHA1-PR8-3-M3-PI**  
Part number: 197 225

**FESTO**

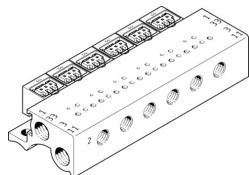

**Data sheet**

Feature	Value
Max. no. of valve positions	8
Operating pressure	0 bar...8 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-10 °C...60 °C
Sub-base mounting type	With through-hole
Pneumatic valve mounting type	With internal thread
Pneumatic connection 1	M7
Pneumatic connection 2	M3
Pneumatic connection 3	M7
Material of sub-base	Wrought aluminum alloy