


Manifold
MHA1-PR2-3-M3-PI-PCB
Part number: 197247

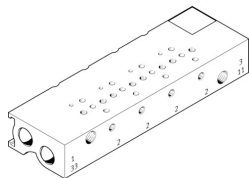

Data sheet

| Feature | Value |
|--|--|
| Max. no. of valve positions | 2 |
| Operating pressure | 0 bar...8 bar |
| Operating medium | Compressed air as per ISO 8573-1:2010 [7:4:4] |
| Information on operating and pilot media | Operation with oil lubrication possible (required for further use) |
| Corrosion resistance class (CRC) | 2 - Moderate corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Ambient temperature | 0 °C...40 °C |
| Pneumatic valve mounting type | With internal thread |
| Pneumatic connection 1 | M5 |
| Pneumatic connection 2 | M3 |
| Pneumatic connection 3 | M5 |
| Material of sub-base | Wrought aluminum alloy |