


**Manifold**  
**MHA1-PR10-3-M3-PI-PCB**  
Part number: 197251

**FESTO**

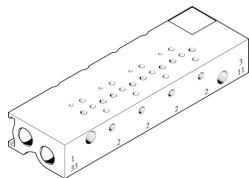

**Data sheet**

Feature	Value
Max. no. of valve positions	10
Operating pressure	0 bar...8 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	0 °C...40 °C
Pneumatic valve mounting type	With internal thread
Pneumatic connection 1	M5
Pneumatic connection 2	M3
Pneumatic connection 3	M5
Material of sub-base	Wrought aluminum alloy