


# Axial kit EAMM-A-L38-60P

Part number: 2037246

FESTO

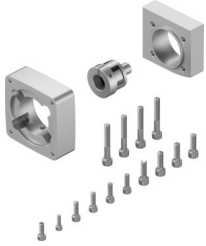

## Data sheet

Feature	Value
Nominal length	37.7 mm
Mounting position	Any
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Mass moment of inertia	3.5 kgmm <sup>2</sup>
Transferable torque	4.4 Nm
Product weight	300 g
Interface code, actuator	L38
Interface code, motor in	60P
Note on materials	RoHS-compliant