


Clevis foot
LBG-80-R3
Part number: 2078797

FESTO

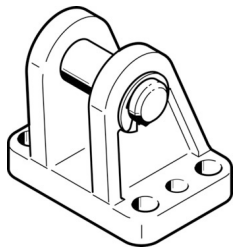

Data sheet

Feature	Value
Size	80
Mounting position	Any
Corrosion resistance class (CRC)	3 - High corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Suitability for the production of Li-ion batteries	Metals with more than 5% by mass of copper, zinc or nickel by mass are excluded from use. Exceptions are nickel in steel, chemically nickel-plated surfaces, printed circuit boards, cables, electrical plug connectors and coils
Ambient temperature	-40 °C...150 °C
Max. load capacity	6 kN
Product weight	1050 g
Note on materials	RoHS-compliant
Mounting material	High-alloy stainless steel
Bolt material	High-alloy stainless steel
Fuse material	High-alloy stainless steel