


Quick coupling plug KS4-CK-6

Part number: 2151

FESTO

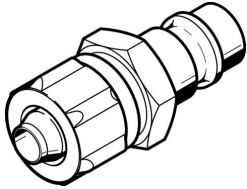

Data sheet

| Feature | Value |
|--|--|
| Nominal width | 4.9 mm |
| Operating pressure for entire temperature range | -0.095 MPa...1.2 MPa -0.95 bar...12 bar -13.775 psi...174 psi |
| Standard nominal flow rate | 432 l/min...495 l/min |
| Nominal flow rate standardized according to ISO 8778 | 468.3 l/min...536.6 l/min |
| Operating medium | Compressed air as per ISO 8573-1:2010 [7:~:] |
| Information on operating and pilot media | Operation with oil lubrication possible |
| Corrosion resistance class (CRC) | 1 - Low corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -10 °C...60 °C |
| Product weight | 26 g |
| Pneumatic connection 1 | for pneumatic tubing outside diameter 8 mm For barbed fitting, inside diameter 6 mm, with union nut |
| Material of union nut | Wrought aluminum alloy, anodized |
| Note on materials | RoHS-compliant |
| Information on materials | Brass, nickel-plated |