


Axial kit
EAMM-A-D32-35A-40P
Part number: 2207441

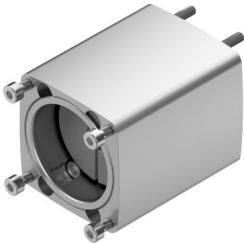

Data sheet

Feature	Value
Nominal length	49.5 mm
Mounting position	Any
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Mass moment of inertia	5.87 kgmm ²
Transferable torque	6.5 Nm
Product weight	160 g
Interface code, actuator	D32C
Interface code, motor in	35A
Note on materials	RoHS-compliant