


Sub-base VABP-S3-26V1G-G18-2M-R3

Part number: 2605075

FESTO

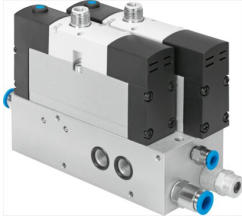

Data sheet

Feature	Value
Width	26 mm
Function port 32	G1/8
Function port 34	G1/8
Pneumatic connection 22	Sub-base G1/8
Pneumatic connection 44	Sub-base G1/8
Mounting position	Any
Operating pressure	0 bar...16 bar
Pilot pressure	3 bar...8 bar
Normal nominal flow rate (normalized to DIN 1343)	800 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [6:4:4]
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Temperature of medium	0 °C...50 °C
Ambient temperature	0 °C...50 °C
Product weight	1200 g
Pilot air port 14	M5
Pneumatic connection 2	G1/8
Pneumatic connection 4	G1/8
Note on materials	RoHS-compliant
Manifold rail material	Wrought aluminum alloy
O-ring material	NBR
Material of screws	Steel