


Bellow cylinder EB-80-45

Part number: 2748904

FESTO

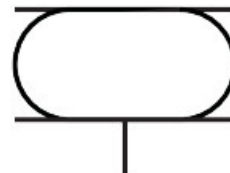

Data sheet

Feature	Value
Size	80
Required installation Ø	95 mm
Stroke	45 mm
Max. height, advanced	110 mm
Max. angle of inclination	15 deg
Max. offset	10 mm
Min. installation height	65 mm
Mode of operation	Single-acting
Operating pressure	0 bar...8 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [:-:4]
Information on operating and pilot media	Operation with oil lubrication not possible
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-40 °C...70 °C
Resetting force	200 N
Product weight	500 g
Type of mounting	With internal thread
Pneumatic connection	G1/4
Note on materials	RoHS-compliant
Bellows material	CR
Housing material	Cast aluminum