


Parallel kit
EAMM-U-145-D100-120G-188
Part number: 2803620

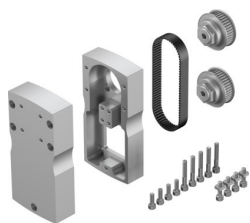

Data sheet

Feature	Value
Size	145
Mounting position	Any
Gear ratio	1:1
Max. rotational speed	4000 rpm
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Mass moment of inertia	2270 kgmm ²
No-load driving torque	2 Nm
Transferable torque	50 Nm
Product weight	12000 g
Interface code, actuator	D100B
Interface code, motor in	120G
Note on materials	RoHS-compliant