


Flange mounting EAHH-V2-32-R1

Part number: 2827587

FESTO

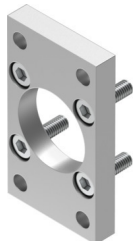

Data sheet

Feature	Value
Size	32
Based on norm	ISO 15552
Corrosion resistance class (CRC)	3 - High corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Suitability for the production of Li-ion batteries	Metals with more than 5% by mass of copper, zinc or nickel by mass are excluded from use. Exceptions are nickel in steel, chemically nickel-plated surfaces, printed circuit boards, cables, electrical plug connectors and coils
Cleanroom class	Statically installed element, no meaningful evaluation possible according to ISO 14644-1
Max. load capacity	1 kN
Product weight	206 g
Note on materials	RoHS-compliant
Plate material	High-alloy stainless steel
Material of screws	High-alloy stainless steel