


**Clevis flange**  
**SNCS-100-R3**  
Part number: 2895925

**FESTO**

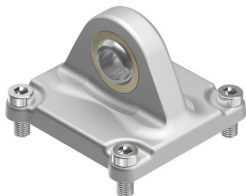

**Data sheet**

Feature	Value
Size	100
Based on norm	ISO 15552 (previously also VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Variants	High corrosion protection
Corrosion resistance class (CRC)	3 - High corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Suitability for the production of Li-ion batteries	Metals with more than 5% by mass of copper, zinc or nickel by mass are excluded from use. Exceptions are nickel in steel, chemically nickel-plated surfaces, printed circuit boards, cables, electrical plug connectors and coils
Ambient temperature	-40 °C...150 °C
Max. load capacity	9 kN
Product weight	684 g
Note on materials	RoHS-compliant
Mounting material	Wrought aluminum alloy With protective coating
Rod end bearing material	PTFE Stainless steel
Material of screws	High-alloy stainless steel