


 
Solenoid valve

MZH-5/3E-M3-L-LED

Part number: 30197

FESTO

Micro Pneumatic, with solenoid coil and manual override, without socket.

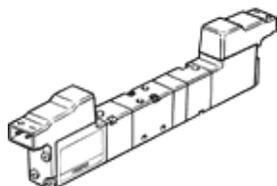

Data sheet

Feature	Value
Valve function	5/3 exhausted
Standard nominal flow rate	40 l/min
Working pressure	2 ... 7 bar
Design structure	Piston slide
Protection class	IP40 with plug socket
Nominal size	1.5 mm
Type of piloting	Piloted
Switching time off	30 ms
Switching time on	5 ms
Duty cycle	100%
Characteristic coil data	24V DC: 0,55W
Operating medium	Dried compressed air, lubricated or unlubricated
Medium temperature	-5 ... 50 °C
Ambient temperature	-5 ... 50 °C
Product weight	50 g
Mounting type	with through hole
Pneumatic connection, port 1	Subbase M3
Pneumatic connection, port 2	Subbase M3
Pneumatic connection, port 3	Subbase M3
Pneumatic connection, port 4	Subbase
Pneumatic connection, port 5	Subbase
Materials information for seals	NBR
Materials information, housing	Aluminum die cast