

 

Solenoid valve

MOZH-3-1,5-L-LED

Part number: 30219

FESTO

Micro Pneumatic with solenoid coil and manual override, without socket.

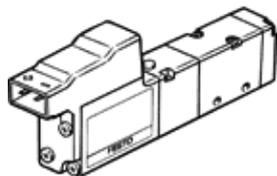

Data sheet

Feature	Value
Valve function	3/2 open, single solenoid
Standard nominal flow rate	80 l/min
Working pressure	2 ... 7 bar
Design structure	Piston slide
Protection class	IP40 with plug socket
Nominal size	1.5 mm
Type of piloting	Piloted
Switching time off	21 ms
Switching time on	7 ms
Duty cycle	100%
Characteristic coil data	24V DC: 0,55W
Operating medium	Dried compressed air, lubricated or unlubricated
Medium temperature	-5 ... 50 °C
Ambient temperature	-5 ... 50 °C
Product weight	30 g
Mounting type	with through hole
Pneumatic connection, port 1	Subbase Manifold module
Pneumatic connection, port 2	Subbase Manifold module
Pneumatic connection, port 3	Subbase Manifold module
Pneumatic connection, port 4	Manifold module
Pneumatic connection, port 5	Manifold module
Materials information for seals	NBR
Materials information, housing	Aluminum die cast