


Clevis foot
LSNSG-50
Part number: 31749

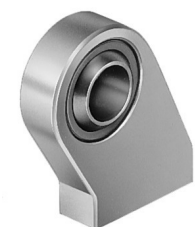

Data sheet

Feature	Value
Size	50
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-40 °C...150 °C
Max. load capacity	2.5 kN
Product weight	300 g
Note on materials	RoHS-compliant
Mounting material	Steel Galvanized
Rod end bearing material	Steel PTFE