


Trunnion support LNZG-63/80

Part number: 32961

FESTO

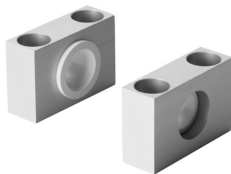

Data sheet

| Feature | Value |
|--|---|
| Size | 63/80 |
| Based on norm | ISO 15552 |
| Corrosion resistance class (CRC) | 2 - Moderate corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Suitability for the production of Li-ion batteries | Product corresponds to Festo's internal product definition for use in battery production: Metals with more than 1% by mass of copper, zinc or nickel are excluded from use. The exceptions are nickel in steel, chemically nickel-plated surfaces, circuit boards, cables, electrical plug connectors and coils |
| Ambient temperature | -40 °C...80 °C |
| Max. load capacity | 6 kN |
| Product weight | 178 g |
| Note on materials | RoHS-compliant |
| Mounting material | Wrought aluminum alloy |
| Material of bearing | Polymer |