


Toggle lever valve KH/O-3-PK-3

Part number: 33003

FESTO

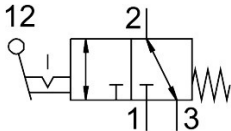

Data sheet

| Feature | Value |
|--|------------------------------|
| Valve function | 3/2, open/closed, monostable |
| Standard nominal flow rate | 80 l/min |
| Pneumatic working port | PK-3 |
| Operating pressure | 0 bar...8 bar |
| Structural design | Piston seat |
| Nominal width | 2.5 mm |
| Type of control | Direct |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -10 °C...60 °C |
| Actuation force in initial position closed | 7.5 N |
| Actuation force in initial position open | 6.5 N |
| Product weight | 20 g |
| Type of mounting | With through-hole |
| Pneumatic connection 1 | PK-3 |
| Pneumatic connection 2 | PK-3 |
| Pneumatic connection 3 | PK-3 |
| Seals material | NBR |
| Housing material | Polymer |