


Guide unit FENG-63-250-KF

Part number: 34517

FESTO

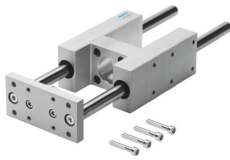

Data sheet

Feature	Value
Size	63
Stroke	250 mm
Mounting position	Any
Guide	Recirculating ball bearing guide
Structural design	Guide
Explosion prevention and protection	Observe the information on the certificate
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-20 °C...80 °C
Max. force Fy	1260 N
Max. force Fy static	1600 N
Max. force Fz	1260 N
Max. force Fz static	1600 N
Max. torque Mx	75 Nm
Max. static moment Mx	95 Nm
Max. torque My	90 Nm
Max. static moment My	115 Nm
Max. torque Mz	90 Nm
Max. static moment Mz	115 Nm
Displacement force	15 N
Product weight	6635 g
Type of mounting	With internal thread
Note on materials	RoHS-compliant
Material of guide component	Tempered steel
Housing material	Wrought aluminum alloy, anodized
Material of yoke plate	Wrought aluminum alloy, anodized