


Guide unit FEN-8/10- -GF

Part number: 35196

FESTO

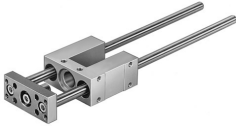

Data sheet

Feature	Value
Size	8/10
Stroke	1 mm...100 mm
Mounting position	Any
Guide	Sliding guide
Structural design	Guide
Explosion prevention and protection	Observe the information on the certificate
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-20 °C...80 °C
Displacement force	15 N
Additional moving mass per 10 mm stroke	8 g
Basic weight with 0 mm stroke	332 g
Additional weight per 10 mm stroke	8 g
Center of gravity of moving mass with 0 mm stroke	30 mm
Center of gravity of moving mass with 10 mm stroke	4.9 mm
Type of mounting	With internal thread
Note on materials	RoHS-compliant
Material of guide component	High-alloy steel
Housing material	Wrought aluminum alloy, anodized
Material of yoke plate	Wrought aluminum alloy, anodized