


Intermediate pressure regulator plate

LR-ZP-B-D-3

Part number: 35426

FESTO

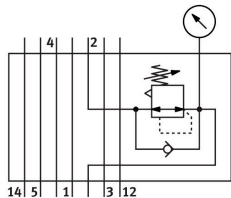

Data sheet

Feature	Value
Based on norm	ISO 5599-1
Integrated function	Pressure regulator
Structural design	Piston
Pressure regulation range MPa	0.05 MPa...1.2 MPa
Pressure regulation range	0.5 bar...12 bar
Pressure regulation range psi	7.25 psi...174 psi
Inlet pressure 1	14 bar
Inlet pressure 1 MPa	1.4 MPa
Inlet pressure 1 psi	203 psi
Certification	UL - Recognized (OL)
LABS (PWIS) conformity	VDMA24364 zone III
Product weight	1220 g
Note on materials	RoHS-compliant
Seals material	NBR
Housing material	Die-cast aluminum Steel