


# Quick coupling plug KS2-CK-4

Part number: 4090

FESTO

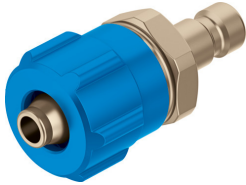

## Data sheet

Feature	Value
Nominal width	2.7 mm
Operating pressure for entire temperature range	-0.095 MPa...1.2 MPa -0.95 bar...12 bar -13.775 psi...174 psi
Standard nominal flow rate	86 l/min...129 l/min
Nominal flow rate standardized according to ISO 8778	93.2 l/min...139.8 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7:~:]
Information on operating and pilot media	Operation with oil lubrication possible
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C...60 °C
Product weight	11 g
Pneumatic connection 1	For pneumatic tubing outside diameter 6 mm For barbed fitting, inside diameter 4 mm, with union nut
Material of union nut	Wrought aluminum alloy, anodized
Note on materials	RoHS-compliant
Information on materials	Brass, nickel-plated