 



Pneumatic valve

VL/O-3-PK-3X2

Part number: 4245

FESTO

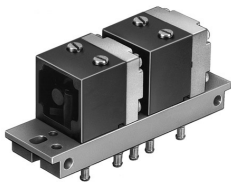

Data sheet

Feature	Value
Valve function	3/2, open, monostable
Standard nominal flow rate	100 l/min
Pneumatic working port	PK-3
Operating pressure	0 bar...8 bar
Structural design	Plate seat
Nominal width	2.5 mm
Switching time off	50 ms
On switching time	12 ms
Operating medium	Compressed air as per ISO 8573-1:2010 [7:::]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Pilot medium	Compressed air as per ISO 8573-1:2010 [7:::]
Ambient temperature	-10 °C...60 °C
Product weight	180 g
Type of mounting	On sub-base On mounting frame With through-hole Optionally:
Pneumatic connection 1	PK-3
Pneumatic connection 4	PK-3
Pneumatic connection 5	PK-3
Material of sub-base	Brass PPS-reinforced
Seals material	NBR
Housing material	Polymer Die-cast zinc