 



Air solenoid valve

MFH-5-PK-3

Part number: 4448

FESTO

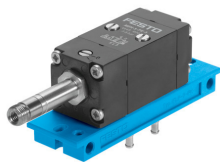

Data sheet

| Feature | Value |
|----------------------------|--|
| Valve function | 5/2, monostable |
| Standard nominal flow rate | 105 l/min |
| Pneumatic working port | PK-3 |
| Operating pressure | 3 bar...8 bar |
| Structural design | Plate seat |
| Nominal width | 2.5 mm |
| Sealing principle | Soft |
| Switching time off | 22 ms |
| On switching time | 10 ms |
| Operating medium | Compressed air as per ISO 8573-1:2010 [7:::] |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Temperature of medium | -10 °C...60 °C |
| Ambient temperature | -5 °C...40 °C |
| Product weight | 270 g |
| Type of mounting | On sub-base On mounting frame With through-hole Optionally: |
| Pneumatic connection 1 | PK-3 |
| Pneumatic connection 2 | PK-3 |
| Pneumatic connection 3 | PK-3 |
| Pneumatic connection 4 | PK-3 |
| Pneumatic connection 5 | PK-3 |
| Note on materials | RoHS-compliant |
| Material of sub-base | Aluminum Anodized |
| Seals material | NBR |
| Housing material | Aluminum Anodized |