 



Pneumatic valve

VL-5-PK-3

Part number: 4504

FESTO

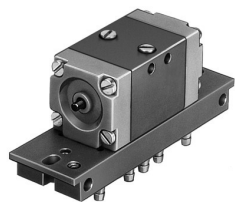

Data sheet

Feature	Value
Valve function	5/2, monostable
Standard nominal flow rate	105 l/min
Pneumatic working port	PK-3
Operating pressure	1.5 bar...8 bar
Structural design	Plate seat
Nominal width	2.5 mm
Switching time off	22 ms
On switching time	15 ms
Operating medium	Compressed air as per ISO 8573-1:2010 [7:::]
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C...60 °C
Product weight	130 g
Type of mounting	On sub-base On mounting frame With through-hole Optionally:
Pneumatic connection 1	PK-3
Pneumatic connection 2	PK-3
Pneumatic connection 3	PK-3
Pneumatic connection 4	PK-3
Pneumatic connection 5	PK-3
Note on materials	RoHS-compliant
Material of sub-base	Brass PPS-reinforced
Seals material	NBR
Housing material	Polymer Die-cast zinc