


Axial kit EAMM-A-T46-100A

Part number: 4624227

FESTO

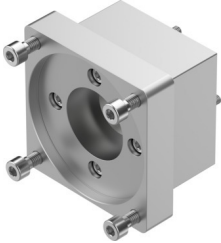

Data sheet

Feature	Value
Nominal length	68.1 mm
Mounting position	Any
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Mass moment of inertia	5.77 kgmm ²
Transferable torque	10 Nm
Product weight	1080 g
Interface code, actuator	T46
Interface code, motor in	100A
Note on materials	RoHS-compliant