 



# Compressed EMC air filter CAMF-C5-FC

Part number: 4825847

**FESTO**

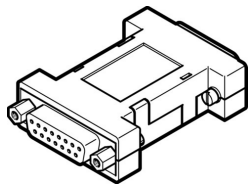

## Data sheet

Feature	Value
DC operating voltage range	0 V...30 V
Nominal operating voltage DC	24 V
Operating voltage range AC	0 V...30 V
Nominal operating voltage AC	24 V
LABS (PWIS) conformity	VDMA24364-B2-L
Degree of protection	IP30
Note on degree of protection	In mounted state
Ambient temperature	-40 °C...80 °C
Note on materials	RoHS-compliant
Electrical connection 1, function	Field device end
Electrical connection 1, design	Rectangular
Electrical connection 1, connection type	Socket
Electrical connection 1, cable outlet	Straight
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	15
Electrical connection 1, occupied pins/wires	8
Electrical connection 2, function	Control side
Electrical connection 2, design	Rectangular
Electrical connection 2, connection type	Plug
Electrical connection 2, cable outlet	Straight
Electrical connection 2, connection technology	Sub-D
Electrical connection 2, number of pins/wires	15
Electrical connection 2, occupied pins/wires	8
Electrical connection 2, type of mounting	2x screw, 4-40 UNC-2A
Protocol	HIPERFACE
Housing colour	Silver
Housing material	Metallized polymer