 



Pneumatic valve

JD-5-PK-3

Part number: 4901

FESTO

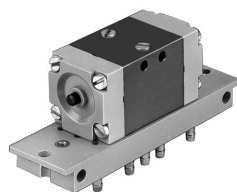

Data sheet

Feature	Value
Valve function	5/2, bistable, dominant
Standard nominal flow rate	105 l/min
Pneumatic working port	PK-3
Operating pressure	1 bar...8 bar
Structural design	Plate seat
Nominal width	2.5 mm
Changeover time	9 ms
Switching time changeover (dominant)	25 ms
Operating medium	Compressed air as per ISO 8573-1:2010 [7:::]
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	0 °C...60 °C
Product weight	130 g
Type of mounting	On sub-base On mounting frame With through-hole Optionally:
Auxiliary pilot air port 12	PK-3
Auxiliary pilot air port 14	PK-3
Pneumatic connection 1	PK-3
Pneumatic connection 2	PK-3
Pneumatic connection 3	PK-3
Pneumatic connection 4	PK-3
Pneumatic connection 5	PK-3
Note on materials	RoHS-compliant
Material of sub-base	Brass PPS-reinforced
Seals material	NBR
Housing material	Polymer Die-cast zinc