


Quick coupling
EAMD-75-51-40-32X32-U
Part number: 5078084

FESTO

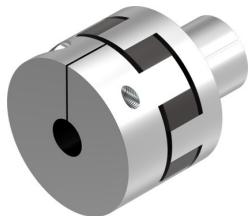

Data sheet

Feature	Value
Diameter of holder 1	40 mm
Diameter of holder 2	32 mm
Size	75
Nominal length	51 mm
Mounting position	Any
Max. rotational speed	4500 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 °C...60 °C
Mass moment of inertia	425 kgmm ²
Transferable torque	200 Nm
Product weight	741 g
Note on materials	RoHS-compliant