


Plug NOCC-M-S-SCRJG2PP-C5-PN

Part number: 5195381

FESTO

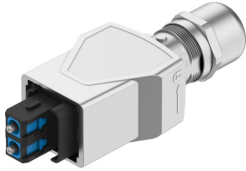

Data sheet

Feature	Value
Conforms to standard	IEC 61754-24
Protocol	Ethernet PROFINET FOC
Additional functions	Meets AIDA requirements
Contact durability	100
Cable outlet	Straight
Product weight	84 g
Optical port 1, connection type	Plug
Optical port 1, style	Rectangular
Optical port 1, connection technology	SC-RJ as per IEC 61754-24
Optical port 1, number of pins/wires	2
Optical connection 1, occupied pins/wires	2
Optical port 1, plug pattern	00995772
Optical port 1, type of mounting	Push-pull with interlock to prevent unintentional pulling
Optical port 1, ferrule diameter	2.5 mm
Optical port 2, connection technology	Lock nut
Tightening torque	0.42 Nm
Wire diameter	0.98 mm...1 mm
Type of wire	Polymer fiber
Wavelength	650 nm
Fire tested	UL94 V-0
Cable diameter	5.5 mm...10 mm
Degree of protection	IP65 IP67
Note on degree of protection	In mounted state
Ambient temperature	-25 °C...70 °C
Storage temperature	-40 °C...70 °C
LABS (PWIS) conformity	VDMA24364-A1-L
Note on materials	RoHS-compliant
Corrosion resistance class (CRC)	1 - Low corrosion stress
Housing material	Die-cast zinc, nickel-plated
Housing colour	Silver

Feature	Value
Seals material	NBR TPE
Material ferrule	Copper alloy