


Vacuum suction cup ESS-40-GT-M10

Part number: 525973

FESTO

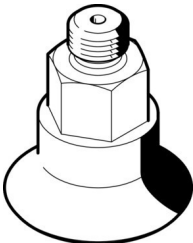

Data sheet

Feature	Value
Suction cup holder height compensator	5.5 mm
Min. workpiece radius	35 mm
Nominal width	2.5 mm
Suction cup diameter	40 mm
Suction cup volume	5.4 cm ³
Mounting position	Any
Classification of suction cup holder	Size 5
Suction cup shape	Round, deep
Operating pressure	-0.95 bar...0 bar
Nominal operating pressure	-0.7 bar
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:::-]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-A1-L
Ambient temperature	-10 °C...80 °C
Holding force at nominal operating pressure	64 N
Lateral force at nominal operating pressure	20 N
Product weight	15 g
Type of mounting	Via vacuum connection
Vacuum connection	M10
Color	Reddish brown
Shore hardness	72 +/- 5
Material of screwed plug	Wrought aluminum alloy
Note on materials	RoHS-compliant
Suction cup material	Vulkollan®