


Air line lubricator MS4-LOE-1/4-R

Part number: 529411

FESTO

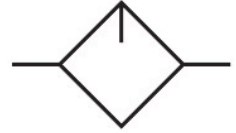

Data sheet

| Feature | Value |
|---|--|
| Size | 4 |
| Series | MS |
| Mounting position | Vertical +/- 5° |
| Structural design | Proportional standard oil mist lubricator |
| Max. oil capacity | 30 cm ³ |
| Bowl guard | Plastic bowl guard |
| Operating pressure | 1 bar...12 bar |
| Minimum flow rate for lubricator function | 40 l/min |
| Standard nominal flow rate | 2200 l/min |
| Operating medium | Compressed air as per ISO 8573-1:2010 [7:4:4] Inert gas |
| Information on operating and pilot media | Operation with oil lubrication possible |
| Corrosion resistance class (CRC) | 2 - Moderate corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Storage temperature | -10 °C...60 °C |
| For use in the food industry | See supplementary material information |
| Temperature of medium | -10 °C...60 °C |
| Oil viscosity | ISO VG 32 |
| Ambient temperature | -10 °C...60 °C |
| Product weight | 194 g |
| Type of mounting | Line installation With accessories Optionally: |
| Pneumatic connection 1 | G1/4 |
| Pneumatic connection 2 | G3/4 |
| Note on materials | RoHS-compliant |
| Housing material | Die-cast aluminum |
| Material of bowl | PC |