


# Quick coupling plug KS4-CK-9

Part number: 531683

FESTO

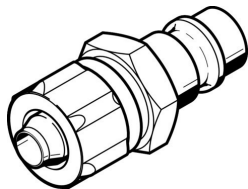

## Data sheet

Feature	Value
Nominal width	7.4 mm
Operating pressure for entire temperature range	-0.095 MPa...1.2 MPa -0.95 bar...12 bar -13.775 psi...174 psi
Standard nominal flow rate	725 l/min...1197 l/min
Nominal flow rate standardized according to ISO 8778	785.9 l/min...1297.5 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7:...]
Information on operating and pilot media	Operation with oil lubrication possible
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C...60 °C
Product weight	26 g
Pneumatic connection 1	For barbed fitting, inside diameter 9 mm, with union nut
Material of union nut	Wrought aluminum alloy, anodized
Note on materials	RoHS-compliant
Information on materials	Brass, nickel-plated