


Branching module MS12-FRM

Part number: 535035

FESTO

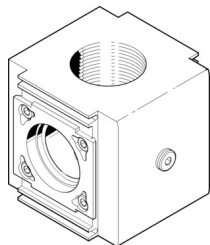

Data sheet

Feature	Value
Mounting position	Any
Structural design	Branching module
Operating pressure	0 bar...20 bar
Standard nominal flow rate in main flow direction 1 -> 2	25000 l/min...42000 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [·:·:·]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-10 °C...60 °C
Temperature of medium	-10 °C...60 °C
Ambient temperature	-10 °C...60 °C
Pneumatic connection 4	G1
Housing material	Die-cast aluminum