


# Sub-base-SET MS12-AQU

Part number: 537140

FESTO

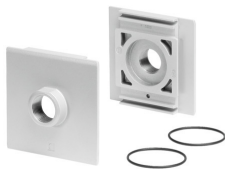

## Data sheet

| Feature                          | Value                                         |
|----------------------------------|-----------------------------------------------|
| Size                             | 12                                            |
| Series                           | MS                                            |
| Mounting position                | Any                                           |
| Operating medium                 | Compressed air as per ISO 8573-1:2010 [7:4:4] |
| Corrosion resistance class (CRC) | 2 - Moderate corrosion stress                 |
| LABS (PWIS) conformity           | VDMA24364-B2-L                                |
| Storage temperature              | -10 °C...60 °C                                |
| Temperature of medium            | -10 °C...60 °C                                |
| Product weight                   | 1300 g                                        |
| Pneumatic connection 1           | 1 1/4 NPT                                     |
| Pneumatic connection 2           | 1 1/4 NPT                                     |
| Note on materials                | RoHS-compliant                                |
| Material of sub-base             | Die-cast aluminum                             |
| Seals material                   | NBR                                           |